




GRK5 Antibody

CATALOG NUMBER: 48-952

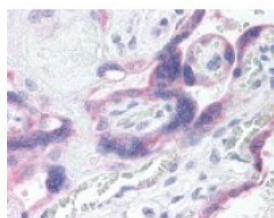

Immunohistochemistry staining of GRK5 in placenta (formalin-fixed paraffin embedded) tissue using GRK5 Antibody.

Specifications

SPECIES REACTIVITY:	Bovine, Chicken, Human, Mouse, Pufferfish, Rat, Zebrafish
TESTED APPLICATIONS:	IHC, WB
APPLICATIONS:	GRK5 antibody can be used in ELISA, Western Blot starting at 1:500 - 1:1000, immunohistochemistry starting at 5 ug/mL, and immunofluorescence starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
SPECIFICITY:	A portion of amino acid 350-400 of human GRK5.
IMMUNOGEN:	A portion of amino acid 350-400 of human GRK5.
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Immunoaffinity Chromatography
PHYSICAL STATE:	Liquid
BUFFER:	PBS, 0.2% gelatin, 0.05% sodium azide.
STORAGE CONDITIONS:	GRK5 antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Polyclonal
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	GRK5, FP2025, GPRK5
ACCESSION NO.:	P34947
PROTEIN GI NO.:	462203
OFFICIAL SYMBOL:	GRK5
GENE ID:	2869

Background

