




ULK1 Antibody

CATALOG NUMBER: 48-950

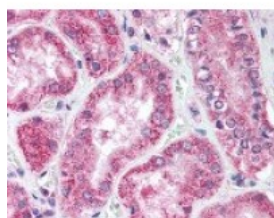

Immunohistochemistry staining of ULK1 in kidney (formalin-fixed paraffin embedded) tissue using ULK1 Antibody.

Specifications

SPECIES REACTIVITY:	Human, Monkey
TESTED APPLICATIONS:	IHC, WB
APPLICATIONS:	ULK1 antibody can be used in ELISA, Western Blot, immunohistochemistry starting at 5 ug/mL, and immunofluorescence starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
SPECIFICITY:	A portion of amino acid 320-370 of human ULK1.
IMMUNOGEN:	A portion of amino acid 320-370 of human ULK1.
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Protein G Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, 0.2% gelatin, 0.05% sodium azide.
STORAGE CONDITIONS:	ULK1 antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Polyclonal
ISOTYPE:	IgG
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	ULK1, ATG1A, ATG1, HATG1, KIAA0722, Unc-51-like kinase 1, Unc51.1, UNC51
ACCESSION NO.:	O75385
PROTEIN GI NO.:	317373288
OFFICIAL SYMBOL:	ULK1
GENE ID:	8408

FOR RESEARCH USE ONLY

December 13, 2016